


# Axial kit EAMM-A-D60-80P-S1

Part number: 2218564

FESTO

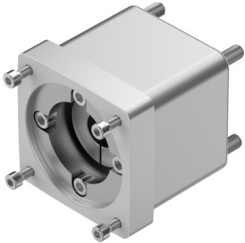

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal length	75.7 mm
Mounting position	Any
Max. rotational speed	6000 rpm
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	34.8 kgmm <sup>2</sup>
Transferable torque	17 Nm
Product weight	1040 g
Interface code, actuator	D60
Interface code, motor in	80P
Note on materials	RoHS-compliant