


Axial kit EAMM-A-R38-60P

Part number: 2224996

FESTO

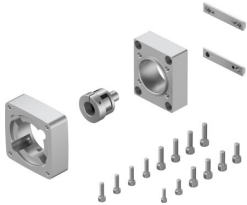

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	41 mm
Mounting position	Any
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	3.5 kgmm ²
Transferable torque	4.4 Nm
Product weight	350 g
Interface code, actuator	R38
Interface code, motor in	60P
Note on materials	RoHS compliant