


# Axial kit EAMM-A-D40-60G

Part number: 2256400

FESTO

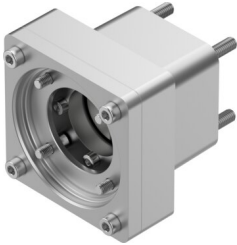

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal length	66.5 mm
Mounting position	Any
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	5.87 kgmm <sup>2</sup>
Transferable torque	12.5 Nm
Product weight	570 g
Interface code, actuator	D40 D40C
Interface code, motor in	60G
Note on materials	RoHS-compliant