


Axial kit EAMM-A-D40-60H-S1

Part number: 2256401

FESTO

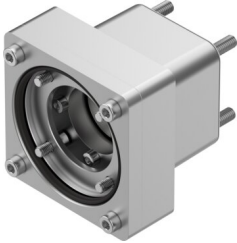

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	67.5 mm
Mounting position	Any
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	5.87 kgmm ²
Transferable torque	12.5 Nm
Product weight	570 g
Interface code, actuator	D40
Interface code, motor in	60H
Note on materials	RoHS-compliant