


# Axial kit EAMM-A-D60-60G-S1

Part number: 2256698

FESTO

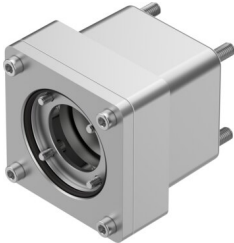

 [General operating condition](#)

## Data sheet

| Feature                  | Value                  |
|--------------------------|------------------------|
| Nominal length           | 75.4 mm                |
| Mounting position        | Any                    |
| Max. rotational speed    | 6000 rpm               |
| LABS (PWIS) conformity   | VDMA24364-B2-L         |
| Storage temperature      | -25 °C ... 60 °C       |
| Relative air humidity    | 0 - 95%                |
| Degree of protection     | IP65                   |
| Ambient temperature      | -10 °C ... 60 °C       |
| Mass moment of inertia   | 34.8 kgmm <sup>2</sup> |
| Transferable torque      | 21 Nm                  |
| Product weight           | 1250 g                 |
| Interface code, actuator | D60<br>D60C            |
| Interface code, motor in | 60G                    |
| Note on materials        | RoHS compliant         |