


Axial kit EAMM-A-D60-70A-S1

Part number: 2256699

FESTO

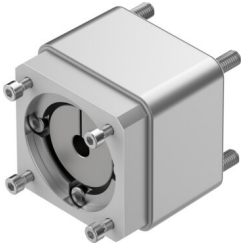

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	64 mm
Mounting position	Any
Max. rotational speed	6000 rpm
LABS (PWIS) conformity	VDMA24364 Zone III
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	34.8 kgmm ²
Transferable torque	17 Nm
Product weight	820 g
Interface code, actuator	D60
Interface code, motor in	70A
Note on materials	RoHS compliant