


# Sub-base VABP-S1-1V1G-G14-2M-R3

Part number: 2614863

FESTO

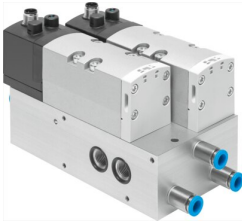

 [General operating condition](#)

## Data sheet

Feature	Value
Width	42 mm
Function port 32	G1/8
Function port 34	G1/8
Pneumatic connection 22	Sub-base G1/4
Pneumatic connection 44	Sub-base G1/4
Mounting position	Any
Operating pressure	0 bar ... 16 bar
Pilot pressure	3 bar ... 8 bar
Normal nominal flow rate (normalized to DIN 1343)	1400 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [6:4:4]
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Temperature of medium	0 °C ... 50 °C
Ambient temperature	0 °C ... 50 °C
Product weight	2480 g
Pilot air port 14	G1/8
Pneumatic connection 2	G1/4
Pneumatic connection 4	G1/4
Note on materials	RoHS-compliant
Manifold rail material	Wrought aluminum alloy
O-ring material	NBR
Material of screws	Steel