



# Branching module PMBL-90-HP3-E

Part number: 2663892

FESTO

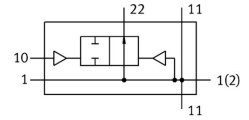

 [General operating condition](#)

## Data sheet

Feature	Value
Size	90
Nominal width DN	36
Series	L
Mounting position	Any
Structural design	Branching module
Symbol	00995259
Operating pressure	0 MPa ... 5 MPa
Operating pressure	0 bar ... 50 bar
Pilot pressure	0 bar ... 50 bar
CE marking (see declaration of conformity)	as per EU pressure equipment directive
UKCA marking (see declaration of conformity)	according to UK regulations for pressure equipment
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364 Zone III
Storage temperature	-10 °C ... 60 °C
For use in the food industry	See supplementary material information
Temperature of medium	5 °C ... 60 °C
Ambient temperature	5 °C ... 60 °C
Product weight	2600 g
Note on materials	RoHS compliant
Seals material	NBR Protective grounding
Housing material	Wrought aluminum alloy