


Axial kit EAMM-A-D50-100A-S1

Part number: 2734288

FESTO

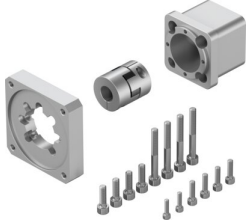

 [General operating condition](#)

Data sheet

| Feature | Value |
|--------------------------|------------------------|
| Nominal length | 84 mm |
| Mounting position | Any |
| Max. rotational speed | 6000 rpm |
| LABS (PWIS) conformity | VDMA24364 Zone III |
| Storage temperature | -25 °C ... 60 °C |
| Relative air humidity | 0 - 95% |
| Degree of protection | IP65 |
| Ambient temperature | -10 °C ... 60 °C |
| Mass moment of inertia | 34.8 kgmm ² |
| Transferable torque | 21 Nm |
| Product weight | 1180 g |
| Interface code, actuator | D50 |
| Interface code, motor in | 100A |
| Note on materials | RoHS compliant |