


Axial kit EAMM-A-D50-100A-S1

Part number: 2734288

FESTO

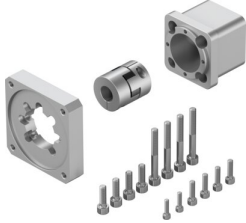

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	84 mm
Mounting position	Any
Max. rotational speed	6000 rpm
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	34.8 kgmm ²
Transferable torque	21 Nm
Product weight	1180 g
Interface code, actuator	D50
Interface code, motor in	100A
Note on materials	RoHS-compliant