


# Sub-base VABP-S1-2V1G-G38-2M-A1

Part number: 2738672

FESTO

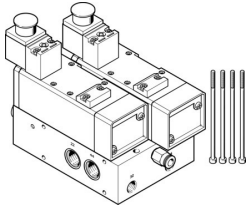

 [General operating condition](#)

## Data sheet

Feature	Value
Width	54 mm
Function port 32	G1/4
Function port 34	G1/4
Pneumatic connection 22	Sub-base G3/8
Pneumatic connection 44	Sub-base G3/8
Mounting position	Any
Operating pressure	0 bar ... 16 bar
Pilot pressure	3 bar ... 8 bar
Normal nominal flow rate (normalized to DIN 1343)	2000 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [6:4:4]
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Temperature of medium	0 °C ... 50 °C
Ambient temperature	0 °C ... 50 °C
Product weight	3400 g
Pilot air port 14	G1/8
Pneumatic connection 2	G3/8
Pneumatic connection 4	G3/8
Note on materials	RoHS-compliant
Manifold rail material	Wrought aluminum alloy
O-ring material	NBR
Material of screws	Steel