


Guide unit EAGF-V2-KF-50-400

Part number: 2784184

FESTO

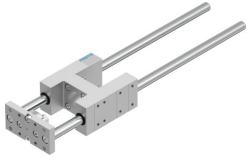

 [General operating condition](#)

Data sheet

Feature	Value
Size	50
Stroke	400 mm
Reversing backlash	0 µm
Mounting position	Any
Guide	Recirculating ball bearing guide
Structural design	Guide
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-20 °C ... 80 °C
Max. force F _y	1260 N
Max. force F _y static	1600 N
Max. force F _z	1260 N
Max. force F _z static	1600 N
Max. torque M _x	65 Nm
Max. static moment M _x	83 Nm
Max. torque M _y	70 Nm
Max. static moment M _y	89 Nm
Max. torque M _z	70 Nm
Max. static moment M _z	89 Nm
Displacement force	15 N
Moving mass	3975 g
Product weight	6019 g
Center of gravity of moving mass with 0 mm stroke	46 mm
Center of gravity of moving mass with 10 mm stroke	4.3 mm
Type of mounting	With internal thread
Note on materials	RoHS-compliant
Material of guide component	Tempered steel
Housing material	Anodized
Material of yoke plate	Steel