


Clevis flange SNCS-125-R3

Part number: 2895926

FESTO

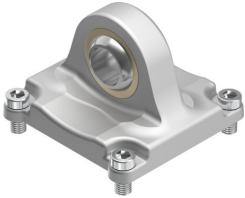

 [General operating condition](#)

Data sheet

| Feature | Value |
|--|--|
| Size | 125 |
| Based on norm | ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290) |
| Variants | High corrosion protection |
| Corrosion resistance class (CRC) | 3 - High corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Suitability for the production of Li-ion batteries | Metals with more than 5% by mass of copper, zinc or nickel are excluded from use. The exceptions are nickel in steel, chemically nickel-plated surfaces, printed circuit boards, cables, electrical plug connectors and coils. |
| Ambient temperature | -40 °C ... 150 °C |
| Product weight | 1369 g |
| Note on materials | RoHS-compliant |
| Mounting material | Wrought aluminum alloy With protective coating |
| Rod end bearing material | PTFE Stainless steel |
| Material of screws | High-alloy stainless steel |