


Plug socket with cable KMF-1-230AC-5

Part number: 30938

FESTO

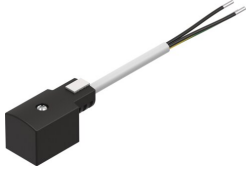

 [General operating condition](#)

Data sheet

Feature	Value
Type of mounting	On air solenoid valve with M3 central screw
Mounting position	Any
Product weight	320 g
Electrical connection	Socket
Nominal operating voltage AC	230 V
Protective earth connection	Available
Cable length	5 m
Cable diameter	6 mm
Cable design	3 x 0.75 mm ²
Degree of protection	IP67 as per IEC 60529
Ambient temperature	-20 °C ... 80 °C
CE marking (see declaration of conformity)	As per EU low voltage directive As per EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions To UK instructions for electrical equipment
LABS (PWIS) conformity	VDMA24364-B2-L
Material of cable sheath	PVC
Housing material	PC POM
Material of pin contacts	Bronze