


Coupling piece KSG-M27X2

Part number: 32967

FESTO

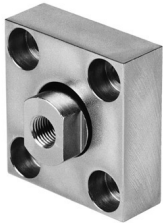

 [General operating condition](#)

Data sheet

Feature	Value
Size	M27x2
Mounting position	Any
Threaded connection	Internal thread M27x2
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Suitability for the production of Li-ion batteries	Metals with more than 1% by mass of copper are excluded from use. Exception are printed circuit boards, cables, electrical connectors and coils
Ambient temperature	-40 °C ... 150 °C
Product weight	1083 g
Note on materials	RoHS-compliant
Mounting material	Steel Galvanized
Threaded coupling material	Steel Galvanized