


# Toggle lever valve KH/O-3-PK-3

Part number: 33003

FESTO

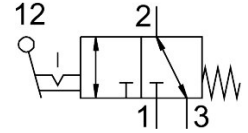

[PDF](#) General operating condition

## Data sheet

| Feature   | Value                        |
|---|------------------------------|
| Valve function                                    | 3/2, open/closed, monostable |
| Normal nominal flow rate (normalized to DIN 1343) | 80 l/min                     |
| Pneumatic working port                            | PK-3                         |
| Operating pressure                                | 0 bar ... 8 bar              |
| Structural design                                 | Piston seat                  |
| Nominal width                                     | 2.5 mm                       |
| Type of control                                   | directly                     |
| Symbol  | 00991285                     |
| LABS (PWIS) conformity                            | VDMA24364-B1/B2-L            |
| Ambient temperature                               | -10 °C ... 60 °C             |
| Actuation force in initial position closed        | 7.5 N                        |
| Actuation force in initial position open          | 6.5 N                        |
| Product weight                                    | 20 g                         |
| Type of mounting                                  | With through-hole            |
| Pneumatic connection 1                            | PK-3                         |
| Pneumatic connection 2                            | PK-3                         |
| Pneumatic connection 3                            | PK-3                         |
| Seals material                                    | NBR                          |
| Housing material                                  | Polymer                      |