


# Foot mounting DAMH-Q12-16

Part number: 3371843

FESTO

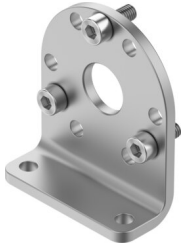

 [General operating condition](#)

## Data sheet

Feature	Value
Size	16
Mounting position	Any
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	0 °C ... 60 °C
Max. tightening torque	4.9 Nm
Product weight	111 g
Type of mounting	With through-hole
Note on materials	RoHS compliant
Bracket material	Steel, galvanized