


Connecting cable KMYZ-2-24-5-LED

Part number: 34998

FESTO

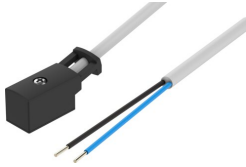

 [General operating condition](#)

Data sheet

Feature	Value
Maritime classification	See certificate
Switching position indication	LED
Type of mounting	On air solenoid valve with self-tapping screw
Mounting position	Any
Product weight	90 g
Electrical connection	2-pin/2-wire Angled socket/cable Rectangular design/open end
Nominal operating voltage DC	24 V
Current rating at 40° C	1 A
Protective earth connection	Not available
Cable length	5 m
Cable characteristic	Standard
Cable diameter	3.4 mm
Cable design	2 x 0.25 mm ²
Degree of protection	IP65
Ambient temperature	-10 °C ... 50 °C
CE marking (see declaration of conformity)	As per EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
LABS (PWIS) conformity	VDMA24364-B2-L
Note on materials	RoHS-compliant
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Material of cable sheath	TPE-U(PUR)
Housing material	PA
Material of pin contacts	Bronze