



# Intermediate pressure regulator plate LR-ZP-P-D-3

Part number: 35968

FESTO

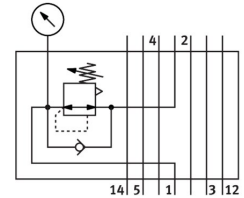

 [General operating condition](#)

## Data sheet

Feature	Value
Based on norm	ISO 5599-1
Structural design	Piston
Integrated function	Pressure regulator
Symbol	00991582
Pressure regulation range MPa	0 MPa ... 1.2 MPa
Pressure regulation range	0 bar ... 12 bar
Pressure regulation range psi	0 psi ... 174 psi
Inlet pressure 1	≤14 bar
Inlet pressure 1 MPa	≤1.4 MPa
Inlet pressure 1 psi	≤203 psi
Certification	UL - Recognized (OL)
LABS (PWIS) conformity	VDMA24364 zone III
Product weight	1220 g
Note on materials	RoHS-compliant
Seals material	NBR
Housing material	Die-cast aluminum Steel