


# One-way flow control valve GGO-1/4-3/8

Part number: 3634

FESTO

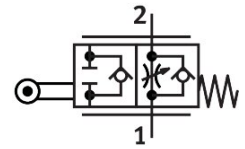

 [General operating condition](#)

## Data sheet

| Feature  | Value  |
|--|--|
| Valve function                                       | One-way flow control function                                      |
| Pneumatic connection 1                               | G1/4   |
| Pneumatic connection 2                               | G1/4   |
| Actuation type                                       | Mechanical   |
| Adjusting element                                    | Roller lever   |
| Type of mounting                                     | With through-hole  |
| Standard nominal flow rate in flow control direction | 950 l/min  |
| Standard nominal flow rate in non-return direction   | 1150 l/min   |
| Operating pressure                                   | 0.03 bar ... 8 bar   |
| Operating pressure                                   | 0.43 psi ... 116 psi   |
| Ambient temperature                                  | -10 °C ... 60 °C   |
| Housing material                                     | Wrought aluminum alloy   |
| Mounting position                                    | Any  |
| Symbol   | 00991466   |
| Operating medium                                     | Compressed air as per ISO 8573-1:2010 [7:-:-]                      |
| Information on operating and pilot media             | Operation with oil lubrication possible (required for further use) |
| LABS (PWIS) conformity                               | VDMA24364-B2-L   |
| Temperature of medium                                | -10 °C ... 60 °C   |
| Product weight                                       | 400 g  |
| Seals material                                       | NBR  |