


# Spiral pneumatic tubing binder PKB-50-BL

Part number: 3656

FESTO

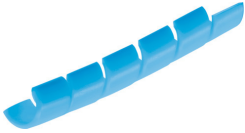

 [General operating condition](#)

## Data sheet

Feature	Value
Size	For tube bundle diameter max. 50 mm
Outside diameter	6 mm
Inside diameter	4 mm
Application note	12 tubes, O.D. 12 mm 28 tubes, O.D. 8 mm 50 tubes, O.D. 6 mm 60 tubes, O.D. 4 mm
Tube length	50 m
LABS (PWIS) conformity	VDMA24364-B2-L
Product weight by length	0.0146 kg/m
Color	Blue
Note on materials	RoHS-compliant
Material of pneumatic tubing	PE