 



# Air solenoid valve

## JMFH-5-PK-3

Part number: 4447

FESTO

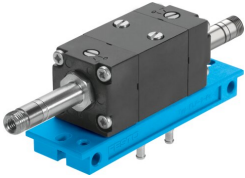

General operating condition

## Data sheet

Feature	Value
Valve function	5/2, bistable
Normal nominal flow rate (normalized to DIN 1343)	105 l/min
Pneumatic working port	PK-3
Operating pressure	2 bar ... 8 bar
Structural design	Plate seat
Nominal width	2.5 mm
Sealing principle	Soft
Symbol	00995753
Changeover time	13 ms
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Temperature of medium	0 °C ... 60 °C
Ambient temperature	0 °C ... 40 °C
Product weight	380 g
Type of mounting	On sub-base On mounting frame With through-hole
Pneumatic connection 1	PK-3
Pneumatic connection 2	PK-3
Pneumatic connection 3	PK-3
Pneumatic connection 4	PK-3
Pneumatic connection 5	PK-3
Note on materials	RoHS-compliant
Material of sub-base	Aluminum Anodized
Seals material	NBR
Housing material	Anodized