


Pushbutton valve F-3-M5

Part number: 4452

FESTO

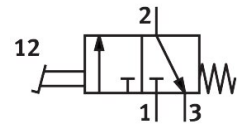

 [General operating condition](#)

Data sheet

Feature	Value
Valve function	3/2-way, closed, monostable
Normal nominal flow rate (normalized to DIN 1343)	80 l/min
Pneumatic working port	M5
Operating pressure	-0.9 bar ... 8 bar
Reset method	Mechanical spring
Type of control	directly
Symbol	00991101
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Product weight	235 g
Pneumatic connection 1	M5
Pneumatic connection 2	M5
Pneumatic connection 3	M5