 



Pneumatic valve VL-5-PK-3

Part number: 4504

FESTO

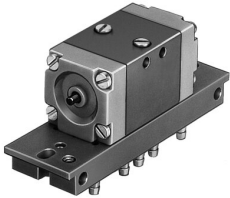

[PDF](#) General operating condition

Data sheet

Feature	Value
Valve function	5/2-way, monostable
Normal nominal flow rate (normalized to DIN 1343)	105 l/min
Pneumatic working port	PK-3
Operating pressure	1.5 bar ... 8 bar
Structural design	Plate seat
Nominal width	2.5 mm
Symbol	00991391
Switching time off	22 ms
On switching time	15 ms
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Product weight	130 g
Type of mounting	On sub-base On mounting frame With through-hole
Pneumatic connection 1	PK-3
Pneumatic connection 2	PK-3
Pneumatic connection 3	PK-3
Pneumatic connection 4	PK-3
Pneumatic connection 5	PK-3
Note on materials	RoHS compliant
Material of sub-base	Brass PPS-reinforced
Seals material	NBR
Housing material	Die-cast zinc