


# Distributor block FR-12-M5

Part number: 4525

FESTO

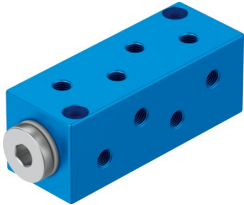

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal width	4.1 mm
Mounting position	Any
Operating pressure for entire temperature range	0 bar ... 16 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Nominal tightening torque	3.5 Nm
Tolerance for nominal tightening torque	± 20%
Product weight	40 g
No. of outlets	12
No. of supply lines	1
Pneumatic connection 1	Internal thread G1/8
Pneumatic connection 2	Internal thread M5
Note on materials	RoHS-compliant
Housing material	Aluminum Anodized