


Air solenoid valve MFH-2-M5

Part number: 4573

FESTO

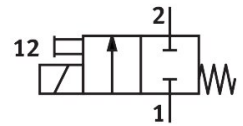

 [General operating condition](#)

Data sheet

Feature	Value
Valve function	2/2-way, closed, monostable
Actuation type	Electrical
Normal nominal flow rate (normalized to DIN 1343)	75 l/min
Pneumatic working port	M5
Operating pressure	0 MPa ... 0.8 MPa
Operating pressure	0 bar ... 8 bar
Structural design	Plate seat
Reset method	Mechanical spring
Nominal width	1.5 mm
Exhaust air function	Cannot be throttled
Sealing principle	Soft
Mounting position	Any
Manual override	Detenting
Type of control	directly
Flow direction	Non-reversible
Symbol	00991398
Switching time off	5 ms
On switching time	6.2 ms
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
LABS (PWIS) conformity	VDMA24364-B2-L
Temperature of medium	-15 °C ... 60 °C
Ambient temperature	-15 °C ... 40 °C
Type of mounting	With through-hole
Pneumatic connection 1	M5
Pneumatic connection 2	M5