


# Axial kit EAMM-A-T46-60P

Part number: 4824833

FESTO

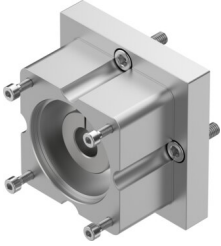

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal length	47 mm
Mounting position	Any
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	3.2 kgmm <sup>2</sup>
Transferable torque	10 Nm
Product weight	397 g
Interface code, actuator	T46
Interface code, motor in	60P 60PA
Note on materials	RoHS-compliant