


Vacuum cup without connector ESV-30-GT

Part number: 526000

FESTO

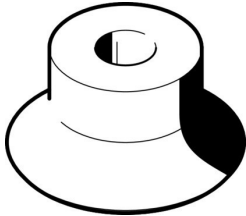

[PDF](#) General operating condition

Data sheet

Feature	Value
Suction cup holder height compensator	3.5 mm
Min. workpiece radius	26 mm
Suction cup diameter	30 mm
Suction cup volume	2.4 cm ³
Mounting position	Any
Structural design	Round, bell-shaped
Symbol	00991485
Suction cup shape	Round, deep
Operating pressure	-0.95 bar ... 0 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
LABS (PWIS) conformity	VDMA24364-A1-L
Ambient temperature	-10 °C ... 80 °C
Breakaway force at 70% vacuum	36 N
Holding force at nominal operating pressure	36 N
Lateral force at nominal operating pressure	13 N
Product weight	4.2 g
Type of mounting	Via vacuum connection
Color	Reddish brown
Shore hardness	72 +/- 5
Note on materials	RoHS-compliant
Suction cup material	Vulkollan®