


# Moment compensator FKC-8/12

Part number: 529350

FESTO

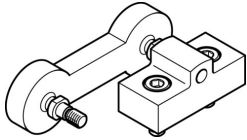

 [General operating condition](#)

## Data sheet

Feature	Value
Size	8/12
Radial deviation +/-	2.5 mm
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Short-term maximum permissible load in direction of force +/-	1100 N
Long-term maximum permissible load in direction of force +/-	550 N
Product weight	29.3 g
Note on materials	RoHS-compliant
Articulated joint material	PA-reinforced
Ball stud material	High-alloy steel
Plate material	Wrought aluminum alloy