


# Branching module MS4-FRM-1/8

Part number: 529559

FESTO

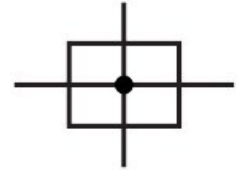

 General operating condition

## Data sheet

Feature	Value
Mounting position	Any
Structural design	Branching module
Symbol	00991510
Operating pressure	0 bar ... 14 bar
Standard nominal flow rate in main flow direction 1 -> 2	1800 l/min
Standard nominal flow rate outlet at top	1600 l/min
Standard nominal flow rate outlet down	1700 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gases
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-10 °C ... 60 °C
For use in the food industry	See supplementary material information
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	165 g
Pneumatic connection 1	G1/8
Pneumatic connection 2	G1/8
Pneumatic connection 3	G1/4
Pneumatic connection 4	G1/4
Note on materials	RoHS compliant
Housing material	Die-cast aluminum