


# Plug FBS-SUB-9-WS-CO-K

Part number: 533783

FESTO

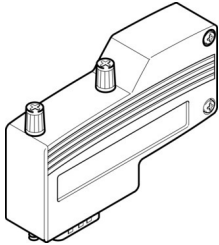

## Data sheet

 [General operating condition](#)

Feature	Value
Width	48 mm
Height	65 mm
Length	16 mm
Type of mounting	4-40 UNC-2B
Product weight	46 g
Fieldbus interface	Sub-D, 9-pin, socket
Electrical connection 1	Socket, Sub-D, 9-pin
Electrical connection 2	Screw terminal
Baud rate	1 Mbit/s
Approved cable diameter	8 mm
Approved cable diameter	8 mm
Connection cross section	1 mm <sup>2</sup>
Degree of protection	IP20
Ambient temperature	0 °C ... 60 °C
Storage temperature	-25 °C ... 80 °C
LABS (PWIS) conformity	VDMA24364-B2-L
Note on materials	RoHS-compliant
Corrosion resistance class (CRC)	1 - Low corrosion stress
Housing material	Metallized polymer