


# Plug FBS-SUB-9-GS-1X9POL-B

Part number: 534497

FESTO

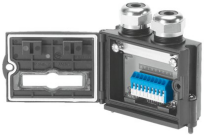

 [General operating condition](#)

## Data sheet

| Feature                 | Value                                                |
|-------------------------|------------------------------------------------------|
| Width                   | 20 mm                                                |
| Height                  | 62 mm                                                |
| Length                  | 61 mm                                                |
| Product weight          | 60 g                                                 |
| Fieldbus interface      | 1x 9 spring-loaded terminals                         |
| Approved cable diameter | 5 mm ... 10 mm                                       |
| Degree of protection    | IP65<br>IP67<br>In mounted state<br>as per IEC 60529 |
| Ambient temperature     | 0 °C ... 50 °C                                       |
| Storage temperature     | -20 °C ... 70 °C                                     |
| Relative air humidity   | 95 %<br>Non-condensing                               |
| LABS (PWIS) conformity  | VDMA24364-B2-L                                       |
| Housing material        | PA-reinforced                                        |
| Material of union nut   | Brass                                                |
| Material of screws      | Steel                                                |
| Seals material          | NBR                                                  |