


Mounting kit SMBR-8-8/100-S6

Part number: 538937

FESTO

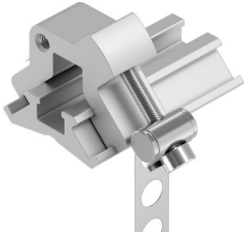

 [General operating condition](#)

Data sheet

Feature	Value
Size	8
Design	for T-slot
Mounting position	Any
for piston Ø	Ø8 - Ø100
Corrosion resistance class (CRC)	4 - Particularly high corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Suitability for the production of Li-ion batteries	Metals with more than 5% by mass of copper, zinc or nickel are excluded from use. The exceptions are nickel in steel, chemically nickel-plated surfaces, printed circuit boards, cables, electrical plug connectors and coils.
Ambient temperature	-20 °C ... 120 °C
Product weight	20 g
Note on materials	RoHS-compliant
Housing material	Anodized High-alloy stainless steel
Material of screws	High-alloy stainless steel