


Vertical pressure supply plate VABF-S4-1-P1A3-N14

Part number: 540172

FESTO

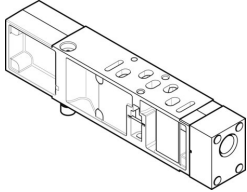

Data sheet

 General operating condition

Feature	Value
Width	26 mm
Based on norm	ISO 15407-2
Mounting position	Any
Symbol	00991883
Operating pressure	1 MPa
Operating pressure	10 bar
CE marking (see declaration of conformity)	As per EU low voltage directive
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP65 NEMA 4
Pilot medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Ambient temperature	-5 °C ... 50 °C
Product weight	191 g
Vertical stacking mounting type	On manifold sub-base On individual sub-base
Pneumatic connection 1	1/4 NPT
Housing material	Die-cast aluminum