


Supply plate VMPA-FB-SP-V

Part number: 541082

FESTO

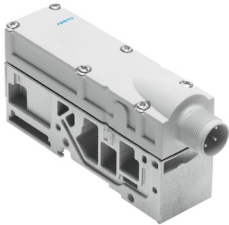

 [General operating condition](#)

Data sheet

| Feature | Value |
|----------------------------------|---------------------------|
| Nominal operating voltage DC | 24 V |
| Permissible voltage fluctuations | +/- 25 % |
| Certification | c UL us - Recognized (OL) |
| Corrosion resistance class (CRC) | 1 - Low corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Degree of protection | IP65 |
| Ambient temperature | -5 °C ... 50 °C |
| Product weight | 200 g |
| Electrical connection | 3-pin M18 |
| Note on materials | RoHS-compliant |
| Cover material | PA-reinforced |
| Housing material | Die-cast aluminum |