


Supply plate VMPA-FB-SP-V

Part number: 541082

FESTO

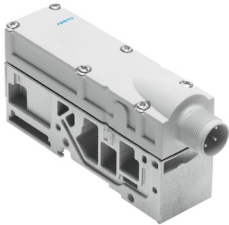

 [General operating condition](#)

Data sheet

Feature	Value
Nominal operating voltage DC	24 V
Permissible voltage fluctuations	+/- 25%
Certification	c UL us - recognized (OL)
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP65
Ambient temperature	-5 °C ... 50 °C
Product weight	200 g
Electrical connection	3-pin M18
Note on materials	RoHS compliant
Cover material	PA-reinforced
Housing material	Die-cast aluminum