


Intermediate position module DADM-DGC-25-A

Part number: 541700

FESTO

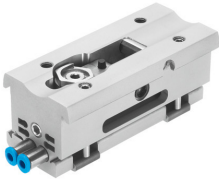

 General operating condition

Data sheet

Feature	Value
Size	25
Mounting position	Any
Position sensing	Via proximity switch
Operating pressure	0.25 MPa ... 0.8 MPa
Operating pressure	2.5 bar ... 8 bar
Operating pressure	36.25 psi ... 116 psi
Max. impact velocity	3 m/s
Maximum pivot time	100 ms
Repetition accuracy	0.02 mm
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Product weight	430 g
Type of mounting	Clamped to cylinder DGC
Pneumatic connection	QS-4
Note on materials	RoHS compliant
Stop screw material	Steel Galvanized
Seals material	NBR
Housing material	Anodized
Lever material	high-alloy stainless steel
Clip material	high-alloy stainless steel
Nut material	Steel Galvanized
Precision adjustment	2 mm
Mode of operation	Double-acting