


# Intermediate position module DADM-DGC-40-A

Part number: 541702

FESTO

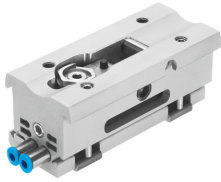

 General operating condition

## Data sheet

Feature	Value
Size	40
Mounting position	Any
Position sensing	For proximity sensor
Operating pressure	0.25 MPa ... 0.8 MPa
Operating pressure	2.5 bar ... 8 bar
Operating pressure	36.25 psi ... 116 psi
Max. impact velocity	3 m/s
Maximum pivot time	300 ms
Repetition accuracy	0.02 mm
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Product weight	970 g
Type of mounting	Clamped on cylinder DGC
Pneumatic connection	M5
Note on materials	RoHS-compliant
Stop screw material	Steel Galvanized
Seals material	TPE-U(PU)
Housing material	Anodized
Lever material	High-alloy stainless steel
Clip material	High-alloy stainless steel
Nut material	Steel Galvanized
Precision adjustment	4 mm
Mode of operation	Double-acting