


# Axial kit EAMM-A-D32-42A

Part number: 543148

FESTO

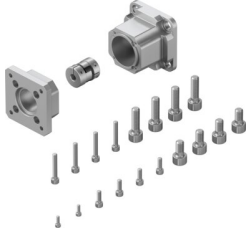

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal length	48 mm
Mounting position	Any
Max. rotational speed	10000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	0.28 kgmm <sup>2</sup>
Transferable torque	1.1 Nm
Product weight	140 g
Interface code, actuator	D32 D32C
Interface code, motor in	42A
Note on materials	RoHS compliant