


# Axial kit EAMM-A-D60-70A

Part number: 543161

FESTO

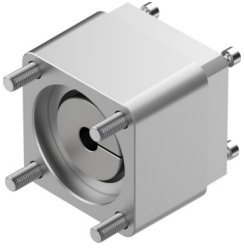

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal length	62.5 mm
Mounting position	Any
Max. rotational speed	6000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	34.8 kgmm <sup>2</sup>
Transferable torque	17 Nm
Product weight	820 g
Interface code, actuator	D60 D60C
Interface code, motor in	70A
Note on materials	RoHS-compliant