


Regulator plate VMPA2-B8-R6C2-C-10

Part number: 543347

FESTO

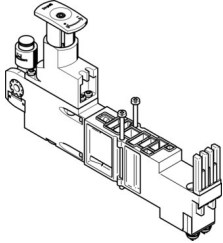

 General operating condition

Data sheet

Feature	Value
Width	21 mm
Mounting position	Any
Pneumatic vertical stacking	Pressure regulator for 2 reversible
Controller function	Outlet pressure constant With secondary exhausting
Symbol	00991558
Optional pressure gauge	Possible
Pressure regulation range	0.5 bar ... 8.5 bar
Inlet pressure 1	0.5 bar ... 10 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP65 as per IEC 60529
Ambient temperature	-5 °C ... 50 °C
Max. tightening torque	0.65 Nm
Product weight	180 g
Vertical stacking mounting type	On manifold sub-base
Pressure gauge connection	With retaining clamp
Note on materials	RoHS-compliant
Material of operator panel	PA
Seals material	NBR
Controller housing material	PA