


Moment compensator FKC-50/63

Part number: 545240

FESTO

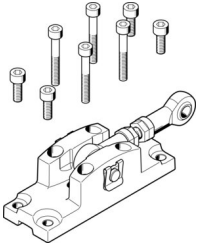

 [General operating condition](#)

Data sheet

| Feature | Value |
|---|-------------------------------|
| Size | 50/63 |
| Radial deviation +/- | 4 mm |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -10 °C ... 60 °C |
| Short-term maximum permissible load in direction of force +/- | 5000 N |
| Long-term maximum permissible load in direction of force +/- | 5000 N |
| Product weight | 1200 g |
| Note on materials | RoHS-compliant |
| Bolt material | High-alloy steel |
| Articulated joint material | High-alloy steel |
| Threaded coupling material | Steel |
| Plate material | Cast aluminum |
| Fuse material | Spring steel |