


# Moment compensator FKC-50/63

Part number: 545240

FESTO

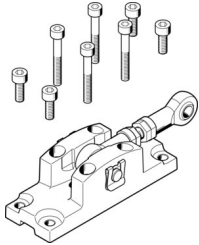

 [General operating condition](#)

## Data sheet

Feature	Value
Size	50/63
Radial deviation +/-	4 mm
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Short-term maximum permissible load in direction of force +/-	5000 N
Long-term maximum permissible load in direction of force +/-	5000 N
Product weight	1200 g
Note on materials	RoHS-compliant
Bolt material	High-alloy steel
Articulated joint material	High-alloy steel
Threaded coupling material	Steel
Plate material	Cast aluminum
Fuse material	Spring steel