



Vacuum security valve ISV-M10

Part number: 545998

FESTO

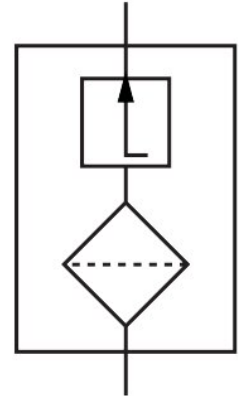

 General operating condition

Data sheet

Feature	Value
Size	M10
Ejector pulse suitability	≤ 0.8 MPa
Ejector pulse suitability	≤ 8 bar
Mounting position	Any
Symbol	00991481
Operating pressure	-0.095 MPa ... 0 MPa
Operating pressure	-0.95 bar ... 0 bar
Required suction rate at -0.5 bar	2 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7::-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Product weight	18 g
Type of mounting	Screw-in
Pneumatic connection 1	M10
Pneumatic connection 2	M10
Material of spring	High-alloy steel
Compressed air filter material	Sintered bronze
Housing material	Wrought aluminum alloy
Float material	POM