


Electrical interface VABE-S6-1LF-C-A4-E

Part number: 549042

FESTO

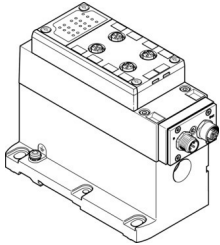

 General operating condition

Data sheet

Feature	Value
Mounting position	Any
Fieldbus interface	Socket, M12x1, 4-pin Plug, M12x1, 4-pin
Max. no. of solenoid coils	4
Number of slaves per device	1
Max. no. of outputs	4
Max. number of inputs	4
Nominal operating voltage DC	24 V
Permissible voltage fluctuations	+/- 10%
CE marking (see declaration of conformity)	As per EU EMC directive As per EU low voltage directive
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C ... 60 °C
Relative air humidity	0 - 90%
Degree of protection	IP65
Ambient temperature	-5 °C ... 50 °C
Product weight	850 g
Electrical actuation	Fieldbus
Electrical connection	Via CPX
Addressing range	1 ... 31 (0) Setting using AS-Interface addressing device
Galvanic isolation fieldbus interface	Optocoupler
Note on materials	RoHS compliant
Seals material	NBR PUR
Housing material	Die-cast aluminum PA