


Axial kit EAMM-A-D32-57A

Part number: 550980

FESTO

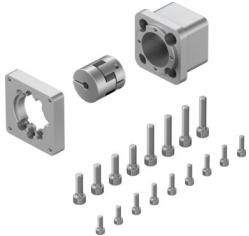

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	50.5 mm
Mounting position	Any
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	5.87 kgmm ²
Transferable torque	6.5 Nm
Product weight	270 g
Interface code, actuator	D32 D32C
Interface code, motor in	57A
Note on materials	RoHS-compliant