


# Axial kit EAMM-A-D40-87A

Part number: 550982

FESTO

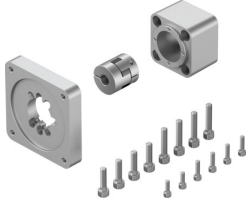

 [General operating condition](#)

## Data sheet

| Feature                  | Value                  |
|--------------------------|------------------------|
| Nominal length           | 54 mm                  |
| Mounting position        | Any                    |
| Max. rotational speed    | 8000 rpm               |
| LABS (PWIS) conformity   | VDMA24364-B2-L         |
| Storage temperature      | -25 °C ... 60 °C       |
| Relative air humidity    | 0 - 95 %               |
| Degree of protection     | IP40                   |
| Ambient temperature      | -10 °C ... 60 °C       |
| Mass moment of inertia   | 5.87 kgmm <sup>2</sup> |
| Transferable torque      | 12.5 Nm                |
| Product weight           | 530 g                  |
| Interface code, actuator | D40<br>D40C            |
| Interface code, motor in | 87A                    |
| Note on materials        | RoHS-compliant         |