


Fiber-optic cable SOOC-TB-F-M4-2-R2

Part number: 552818

FESTO

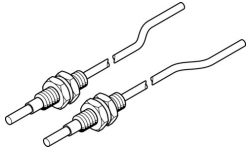

 General operating condition

Data sheet

Feature	Value
Note on materials	RoHS compliant
Method of measurement	Through-beam sensor
Minimum object diameter	0.15 mm
Special feature of fibre-optic cable	Flexible
Working range	300 mm
Ambient temperature	-40 °C ... 70 °C
Head size	M4
Fibre-optic cable length	2 m
Min. bending radius	2 mm
Max. tightening torque	2 Nm
Outside diameter	2.2 mm
Housing material	Brass, nickel-plated
Fiber-optic cable	Protective grounding
Degree of protection	IP66
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364 Zone III