


Fiber-optic cable SOOC-TB-P-M4-1-R15

Part number: 552825

FESTO

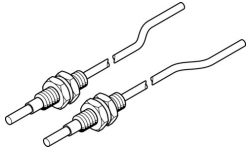

 General operating condition

Data sheet

Feature	Value
Note on materials	RoHS compliant
Method of measurement	Through-beam sensor
Minimum object diameter	0.2 mm
Special feature of fibre-optic cable	Precision
Working range	120 mm
Ambient temperature	-55 °C ... 70 °C
Head size	M4
Fibre-optic cable length	1 m
Min. bending radius	15 mm
Max. tightening torque	2 Nm
Outside diameter	2.2 mm
Housing material	high-alloy stainless steel
Fiber-optic cable	Protective grounding
Degree of protection	IP66
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364 Zone III