


# Vacuum filter VAF-DB-3/8

Part number: 553140

FESTO

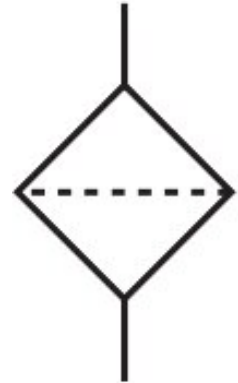

 [General operating condition](#)

## Data sheet

Feature	Value
Mounting position	Vertical
Grade of filtration	80 µm
Symbol	00991483
Operating pressure	-0.95 bar ... 0 bar
Information on operating pressure	Only for use in open vacuum systems
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364 Zone III
Ambient temperature	-5 °C ... 50 °C
Max. tightening torque	15.3 Nm
Product weight	156 g
Type of mounting	With wall/surface bracket
Pneumatic connection	G3/8
Vacuum connection	G3/8
Note on materials	RoHS compliant
Seals material	NBR
Compressed air filter material	Protective grounding
Housing material	Reinforced PP
Material of bowl	PA
Ejector pulse suitability	≤7 bar